

PatchRunner™2 Enhanced Vertical Cable Manager with Vertical Patching

specifications

The Patchrunner™2 Enhanced Vertical Cable Manager with Vertical Patching shall consist of a metal backbone with cable management fingers that align with EIA rack spacing. The backbone shall be an open design that will accept 19" EIA accessories such as patch panels, strain relief pbars, blanking panels, and a PDU mounted vertically in a zero RU format. The fingers shall be molded out of plastic and provide integral bend radius control throughout the entire length. Finger sections shall be removable. The manager shall accept a metal, hinged, push-to-close door that can open to the right or left. The vertical panel shall be able to manage all the cable on the rack without the aid of horizontal cable managers.



PE2VD12 PE2VFD12

key features and benefits

Integral EIA 19" Zero RU Mounting	Allows mounting of many standard EIA 19" accessories such as patch panels, strain relief bars, and blanking panels, within the vertical channel of the manager
26.8" Extra Deep Manager	26.8" depth at a 60/40 split provides the highest capacity for latest high performance switches and Category 6A cabling
Improved Door Function	"Push-to-close" door design allows for easy operation
Dual Hinged Doors are Included	Doors ship with manager, simplifying ordering process with less packaging waste
Color Options	Managers and doors now available in black and white as standard
Highest Density with Increased Cable Capacity	Up to 45% more usable capacity over PR2V manager
Bend Radius Control	Fingers support cables as they transition to vertical pathway while maintaining cable bend radius control, ensuring network performance and system reliability
Optional Accessories	Allows for personalization based on network equipment needs

applications

Panduit Patchrunner™2 Enhanced Vertical Cable Manager with Vertical Patching is designed to manage, protect, and showcase cabling for the latest high performance switching equipment. Ideal for the highest-density cabling environments, the depth of the cable manager, and the integral Zero RU patching within the vertical channel saves up to half the space of a traditional

cabling management system. This reduction in square footage combined with simplified part number ordering leads to cost savings for the overall network infrastructure. When used with Panduit connectivity, patch cords, and racks, the user receives a complete cable management solution that maximizes density while minimizing the area required for their network.

Vertical Cable Managers – 7 Foot

Double-sided with two doors:

6" wide:	PE2VD06^
8" wide:	PE2VD08^
10" wide:	PE2VD10^
12" wide:	PE2VD12^

Double-sided with one door:

6" wide:	PE2VSD06^
8" wide:	PE2VSD08^
10" wide:	PE2VSD10^
12" wide:	PE2VSD12^

Single-sided with one door:

6" wide:	PE2VFD06^
8" wide:	PE2VFD08^
10" wide:	PE2VFD10^
12" wide:	PE2VFD12^

Vertical Cable Managers – 8 Foot

Double-sided with two Doors:

6" wide:	PE2VD0696^
8" wide:	PE2VD0896^
10" wide:	PE2VD1096^
12" wide:	PE2VD1296^

Double-sided with one door:

6" wide:	PE2VSD0696^
8" wide:	PE2VSD0896^
10" wide:	PE2VSD1096^
12" wide:	PE2VSD1296^

Single-sided with one door:

6" wide:	PE2VFD0696^
8" wide:	PE2VFD0896^
10" wide:	PE2VFD1096^
12" wide:	PE2VFD1296^

Accessories

7" front slack management spool:	PRSP7
5" rear slack management spool:	PRSP5
End Panel:	PE2VEP^
Cable retainer:	WR5E-X

Standard EIA Racks – 7ft.

2-Post Aluminum Rack with #12-24 threaded Rails:	R2P^
4-post Steel rack with #12-24 threaded rails:	R4P^
4-post steel rack with cage nut rails:	R4PCN^

*For part numbers 8 feet tall, add "96" to end of part number. Ex: PE2VEP96 or R2P96

^For part numbers in white, add "WH" to end of part number. Ex: PE2VD06WH or R2PWH

PatchRunner™ 2 Enhanced Vertical Cable Manager with Vertical Patching

technical information

7 Foot Vertical Cable Managers


Part Number	Height	Width	Depth	No. of Rack Units
Double Sided				
PE2VD06*	84.0" (2130mm)	6.0" (152mm)	26.8" (681mm)	45
PE2VD08*	84.0" (2130mm)	8.0" (203mm)	26.8" (681mm)	
PE2VD10*	84.0" (2130mm)	10.0" (254mm)	26.8" (681mm)	
PE2VD12*	84.0" (2130mm)	12.0" (305mm)	26.8" (681mm)	
Single Sided				
PE2VFD06*	84.0" (2130mm)	6.0" (152mm)	16.3" (415mm)	45
PE2VFD08*	84.0" (2130mm)	8.0" (203mm)	16.3" (415mm)	
PE2VFD10*	84.0" (2130mm)	10.0" (254mm)	16.3" (415mm)	
PE2VFD12*	84.0" (2130mm)	12.0" (305mm)	16.3" (415mm)	
Double Sided - 1 Door				
PE2VSD06*	84.0" (2130mm)	6.0" (152mm)	26.8" (681mm)	45
PE2VSD08*	84.0" (2130mm)	8.0" (203mm)	26.8" (681mm)	
PE2VSD10*	84.0" (2130mm)	10.0" (254mm)	26.8" (681mm)	
PE2VSD12*	84.0" (2130mm)	12.0" (305mm)	26.8" (681mm)	

* Add "WH" to end of part numbers for white products

8 Foot Vertical Cable Managers

Part Number	Height	Width	Depth	No. of Rack Units
Double Sided				
PE2VD0696*	96.0" (2435mm)	6.0" (152mm)	26.8" (681mm)	52
PE2VD0896*	96.0" (2435mm)	8.0" (203mm)	26.8" (681mm)	
PE2VD1096*	96.0" (2435mm)	10.0" (254mm)	26.8" (681mm)	
PE2VD1296*	96.0" (2435mm)	12.0" (305mm)	26.8" (681mm)	
Single Sided				
PE2VFD0696*	96.0" (2435mm)	6.0" (152mm)	16.3" (415mm)	52
PE2VFD0896*	96.0" (2435mm)	8.0" (203mm)	16.3" (415mm)	
PE2VFD1096*	96.0" (2435mm)	10.0" (254mm)	16.3" (415mm)	
PE2VFD1296*	96.0" (2435mm)	12.0" (305mm)	16.3" (415mm)	
Double Sided - 1 Door				
PE2VSD0696*	96.0" (2435mm)	6.0" (152mm)	26.8" (681mm)	52
PE2VSD0896*	96.0" (2435mm)	8.0" (203mm)	26.8" (681mm)	
PE2VSD1096*	96.0" (2435mm)	10.0" (254mm)	26.8" (681mm)	
PE2VSD1296*	96.0" (2435mm)	12.0" (305mm)	26.8" (681mm)	

* Add "WH" to end of part numbers for white products

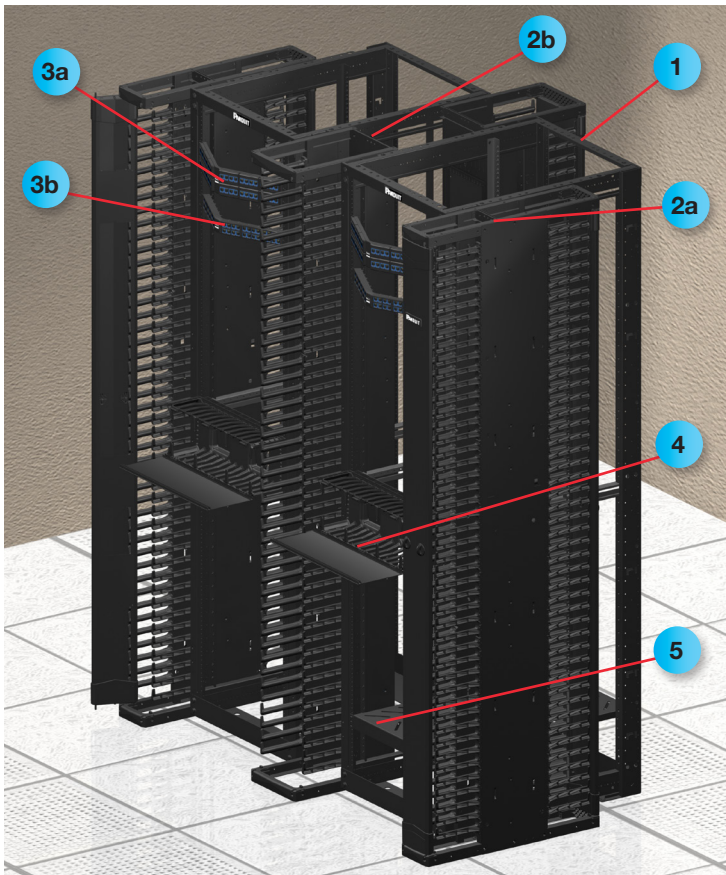

4 Post Rack

1. R4P - 19" EIA Rack, 45RU x 30" Depth

PatchRunner™2 Enhanced Vertical Cable Managers

2a. PE2VD06 - 6" wide

2b. PE2VFD08 - 8" wide

Angled Modular Patch Panels

3a. CPPLA48WBLY - 2 RU, 48-Port

3b. CPPLA24WBLY - 1 RU, 24-Port

Cable Management Accessories

4. NM4 - Cable Manager, 4 RU

5. RSHLF - 4 Post Rack Mount Shelf

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

PANDUIT®

Visit us at www.panduit.com

edi@panduit.com

©2018 Panduit Corp.
ALL RIGHTS RESERVED.
CMSPO4--WW-ENG
12/2018