

# MP300/E

PXE™ SERIES Mobile Printer

Product Bulletin

## Full-Feature Solutions and Industrial Grade Capability



**PANDUIT™**

**EPSON**  
EXCEED YOUR VISION

PORTABLE LABEL PRINTER PARTNER

## PXE™ SERIES Mobile Printers

Do your job smarter, faster and easier with PXE Series Mobile Printers. This full line of advanced identification printers combine Panduit's industry-leading performance and field-tested durability with Epson's world-class printing technology.



### MP300 Mobile Label Printer

Industrial grade finished marking solutions for network and electrical contractors and safety professionals.

#### FEATURES:

- Shared MP Cassette Platform
- 360 dpi print resolution
- Automatic cutter with full and half cut
- Fast 1.4 in./sec. print speed
- Up to 1.5 in. wide label sizes
- Prints *die-cut* and *continuous* labels
- USB connectivity
- Prints from Easy-Mark Plus™ Software
- Magnetic attachment accessory
- Rechargeable battery pack

### Easy-Mark Plus™ Software



- Common templates to easily create and print all electrical and network applications
- 11 languages included
- Available for USB flash drive, CD, web download or network server-based version
- Works with Panduit portable and desktop thermal transfer printers, Panduit embossing systems and other laser jet and ink jet printers
- A free 90 day trial version is available from [www.panduit.com](http://www.panduit.com)

# PANDUIT™

# EPSON

EXCEED YOUR VISION

PORTABLE LABEL PRINTER PARTNER

#### Epson™ Print Technology

Epson is a global technology leader dedicated to connecting people, things and information with efficient, compact and precision technologies.


#### Panduit™ Labeling and Software Expertise

Panduit creates leading-edge labeling solutions for electrical and network environments, from the data center to the telecom room, the jobsite to the plant floor.

### Highlights



Self-Laminating Labels

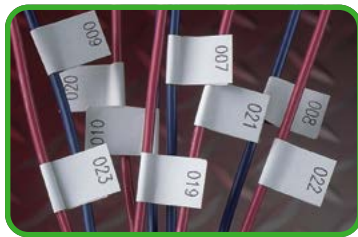


Flag Labels



High printing speed



Half cut function

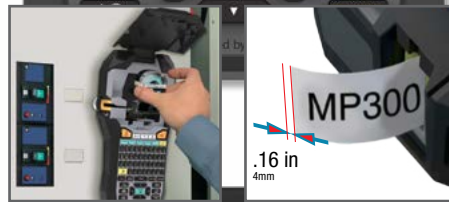

Front loading cassette



Less margin waste



Magnetic attachment




Label retention after cutting



Patch Panel / Face Plate Labels



Mixed Length Labels

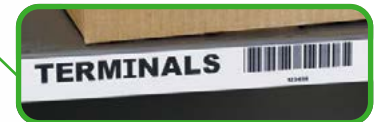

Continuous Tapes

### Ordering Information

#### Printers and Accessories



MP300



MP300-CASE

Part Number	Description
<a href="#">MP300/E</a>	Includes MP300 printer, one (1) cassette of S100X150VAM self-laminating labels, rechargeable Li-Ion battery pack, hard carrying case, power adapter (MP300-AC), USB cable and magnetic attachments. For use outside of North America.
<a href="#">MP-BATT</a>	The MP-BATT Li-Ion Rechargeable Replacement Battery Pack is designed for use with the MP200 and MP300 mobile printers. The battery pack is RoHS Compliant. The battery is gray and comes 1 per package.
<a href="#">MP-CASE</a>	Replacement Hard Carrying Case designed for the MP200 and MP300 mobile printers. The case is RoHS Compliant. The case is 15.57 inches L x 11.74 inches W (395.4 mm x 298.4 mm). It is black and comes 1 per package.
<a href="#">PTR-CLN</a>	Printer cleaning kit — contains (1) cleaning pen, (8) cleaning solution soaked wipes, (8) foam swabs pre-saturated with cleaning solution, MSDS, and cleaning instructions



EMPLUS

Part Number	Description
<a href="#">EMPLUS-CD</a>	Easy-Mark Plus™ Labeling Software, CD-ROM.
<a href="#">EMPLUS-DL</a>	Easy-Mark Plus™ Labeling Software, online download.
<a href="#">EMPLUS-2GO</a>	Easy-Mark Plus™ Portable Application, USB flash drive.
<a href="#">EMPLUS-SERVER</a>	Easy-Mark Plus™ Labeling Software, networkable server based version.

Easy-Mark Plus Labeling Software is sold separately, not included with PXE Printers

### Ordering Information



#### Die-Cut Self Laminating Label Cassettes

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Self-laminating adhesive labels for wire/cable identification include a white print-on area and clear overlaminate



Self-Laminating Vinyl  
(VA)



-40°F to 150°F  
(-40°C to 66°C)

Part Number	Description	Quantity of Labels Per Cassette	Printer Compatibility				Print-on Area Color	Width		Length		Print-on Area Height		Min. Cable O.D.		Max. Cable O.D.		Wire/Cable Size Range	Std. Pkg. Qty.	Std. Ctn. Qty.
			MP 75	MP 100	MP 200	MP 300		In.	mm	Ft.	m	In.	mm	In.	mm	In.	mm			
<a href="#">S050X075VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, .50" W x .75" H, .25" Print On Area, Clear/White.	425							0.75	19.1	0.25	6.4	0.08	2.0	0.16	4.0	18 - 14 AWG			
<a href="#">S050X125VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, .50" W x 1.25" H, .38" Print On Area, Clear/White.	200						0.5	12.7	1.25	31.8	0.38	9.7	0.12	3.1	0.28	7.0	12 - 10 AWG		
<a href="#">S050X150VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, .50" W x 1.50" H, .50" Print On Area, Clear/White.	175						1.5	38.1	0.50	12.7	0.16	4.0	0.32	8.1	Cat. 5e/ Cat. 6				
<a href="#">S100X075VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, 1.0" W x .75" H, .25" Print On Area, Clear/White.	300							0.75	19.1	0.25	6.4	0.08	2.0	0.16	4.0	18 - 14 AWG			
<a href="#">S100X125VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, 1.0" W x 1.25" H, .38" Print On Area, Clear/White.	200	N	N	N	Y	Black on White		1.25	31.8	0.38	9.7	0.12	3.1	0.28	7.0	12 - 10 AWG	1	5	
<a href="#">S100X150VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, 1.0" W x 1.50" H, .50" Print On Area, Clear/White.	175						1.0	25.4	1.5	38.1	0.50	12.7	0.16	4.0	0.32	8.1	Cat. 5e/ Cat. 6		
<a href="#">S100X225VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, 1.0" W x 2.25" H, .75" Print On Area, Clear/White.	125							2.25	57.2	0.75	19.1	0.24	6.1	0.48	12.2	8 - 4 AWG			
<a href="#">S100X400VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, 1.0" W x 4.0" H, 1.0" Print On Area, Clear/White.	70							4.0	101.6	1.0	25.4	0.32	8.1	0.95	24.3	2 - 1 AWG			
<a href="#">S100X650VAM</a>	MP Cassette, Self-Laminating Label, Vinyl, 1.0" W x 6.50" H, 1.5" Print On Area, Clear/White.	45							6.5	165.1	1.5	38.1	0.48	12.2	1.59	40.4	1/0-250 MCM			

Representative offering only, visit [www.panduit.com](http://www.panduit.com) for complete listing of products.

#### LabelCore™ Fiber Optic Cable Identification System



- Provides a larger labeling surface on small fiber cables and allows legends to be clearly seen
- Sleeves are made of flexible PVC material
- Locate sleeve on straight section of cable at least 2 inches from fiber boot

 
Part Number	Color	Description	Std. Pkg. Qty.
<a href="#">NWSLC-2Y</a>	Yellow	Yellow cable identification sleeve for 2mm simplex fiber cable, 1" long, use with labels: <a href="#">S100X150YAJ</a> (Laser/Inkjet); <a href="#">S100X150VAM</a> (MP300 Hand-held Printer); <a href="#">S100X150VA1Y</a> or S100X150VATY (Thermal Transfer Printer).	100
<a href="#">NWSLC-2Y-AQ</a>	Aqua	Aqua cable identification sleeve for 2mm simplex cable, 1" long, use with labels: <a href="#">S100X150YAJ</a> (Laser/Inkjet); <a href="#">S100X150VAM</a> (MP300 Hand-held Printer); <a href="#">S100X150VA1Y</a> or S100X150VATY (Thermal Transfer Printer).	
<a href="#">NWSLC-3Y</a>	Orange	Orange cable identification sleeve for 3mm simplex cable, 1" long, use with labels: <a href="#">S100X150YAJ</a> (Laser/Inkjet); <a href="#">S100X150VAM</a> (MP300 Hand-held Printer); <a href="#">S100X150VA1Y</a> or S100X150VATY (Thermal Transfer Printer).	
<a href="#">NWSLC-7Y</a>	White	White cable identification sleeve for 3mm duplex fiber cable, 1" long, use with labels: <a href="#">S100X225YAJ</a> (Laser/Inkjet); <a href="#">S100X225VAM</a> (MP300 Hand-held Printer); <a href="#">S100X225VATY</a> or <a href="#">S200X225VATY</a> (Thermal Transfer Printer).	

### Ordering Information



#### Turn-Tell™ Label Cassettes **PATENTED**

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Innovative label design allows labels to rotate for visibility from any angle, and for repositioning on the wire/cable to align legends and improve aesthetics
- Labels can be easily installed on existing terminated wires and assemblies without disconnecting the wires/cables



Polymer Film  
(V1)



-40°F to 200°F  
(-40°C to 93°C)

Part Number	Description	Labels per Cassette	Printer Compatibility				Print-On Area Color	Width		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
			MP75	MP100	MP200	MP300		In.	mm	In.	mm		
<a href="#">R100X075V1M</a>	MP Cassette, Turn-Tell Self-Lam Label, Vinyl, 1.0" W x .75" H, .25" Print On Area, Clear/White	175								0.75	19.1		
<a href="#">R100X125V1M</a>	MP Cassette, Turn-Tell Self-Lam Label, Vinyl, 1.0" W x 1.25" H, .38" Print On Area, Clear/White	125								1.25	31.8		
<a href="#">R100X150V1M</a>	MP Cassette, Turn-Tell Self-Lam Label, Vinyl, 1.0" W x 1.50" H, .50" Print On Area, Clear/White	100	N	N	N	Y	Black on White	1.0	25.4	1.5	38.1	1	5
<a href="#">R100X225V1M</a>	MP Cassette, Turn-Tell Self-Lam Label, Vinyl, 1.0" W x 2.25" H, .75" Print On Area, Clear/White	75								2.25	57.2		

Representative offering only, visit [www.panduit.com](http://www.panduit.com) for complete listing of products.



#### Continuous Self-Laminating Labels

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Self-laminating adhesive labels for wire/cable identification include a white print-on area and clear over-laminate



Self-Laminating Vinyl  
(VA)



-40°F to 150°F  
(-40°C to 66°C)

Part Number	Description	Printer Compatibility				Print-On Area Color	Width		Length		Print-On Area Width		Min. Cable O.D.		Max. Cable O.D.		Wire/Cable Size Range	Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m	In.	mm	In.	mm	In.	mm			
<a href="#">S000X100VAM</a>	MP Cassette, Continuous Self-Lam Tape, Vinyl, 1.0" W x 26' L, White	N	Y	Y	Y	White	0.945	24	26.2	8.0	0.315	8	0.10	2.5	0.20	5.1	12 – 10 AWG	1	5
<a href="#">S000X150VAM</a>	MP Cassette, Continuous Self-Lam Tape, Vinyl, 1.5" W x 26' L, White	N	N	N	Y	White	1.417	36	26.2	8.0	0.512	13.0	0.16	4.0	0.32	8.1	Cat. 5e/ Cat. 6	1	5


Representative offering only, visit [www.panduit.com](http://www.panduit.com) for complete listing of products.


**Ordering Information**



**Non-Laminated Label Cassettes**

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Non-laminated adhesive labels for wire/cable identification

 Nylon Cloth (C1M)

 -65°F to 275°F (-54°C to 135°C)

Part Number	Description	Printer Compatibility				Print-On Area Color	Height		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
<a href="#">T050X000C1M-BK</a>	MP Cassette, Continuous Tape, Nylon Cloth, 0.50" W x 19' L, Black on White	Y			Y	Black on White	0.465	11.82	19	6	1	5
<a href="#">T075X000C1M-BK</a>	MP Cassette, Continuous Tape, Nylon Cloth, 0.75" W x 19' L, Black on White						N	Y				
<a href="#">T100X000C1M-BK</a>	MP Cassette, Continuous Tape, Nylon Cloth, 1.00" W x 19' L, Black on White	N					0.938	23.82				

Representative offering only, visit [www.panduit.com](http://www.panduit.com) for complete listing of products.



**Like what you see?  
Want more?**

Visit [panduit.com/mobileprinters](http://panduit.com/mobileprinters) for the full offering of Panduit products

### Ordering Information



#### Continuous Heat Shrink Labels

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Non-adhesive flattened heat shrinkable polyolefin for wire/cable identification



Heat Shrinkable Polyolefin  
3:1 Heat Shrink Ratio (H1, H2)



Heat Shrinkable Polyolefin  
2:1 Heat Shrink Ratio (HP, HX)

-40°F to 257°F  
(-40°C to 125°C)

-67°F to 257°F  
(-55°C to 125°C)

Part Number	Description	Shrink Ratio	Mil Spec	Printer Compatibility				Ribbon & Material Color	Width		Length		Min. Cable O.D.		Max. Cable O.D.		Wire/Cable Size Range	Std. Pkg. Qty.	Std. Ctn. Qty.
				MP75	MP100	MP200	MP300		In.	mm	Ft.	m	In.	mm	In.	mm			
<a href="#">H000X025H1M</a>	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .25" W x 8' L, White	3:1	Y	Y				Black on White	0.27	6.8			0.06	1.4	0.16	4.1	22 - 18 AWG		
<a href="#">H000X025H2M</a>	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .25" W x 8' L, Yellow							Black on Yellow											
<a href="#">H000X034H1M</a>	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .34" W x 8' L, White							Black on White											
<a href="#">H000X034H2M</a>	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .34" W x 8' L, Yellow							Black on Yellow											
<a href="#">H000X044H1M</a>	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .44" W x 8' L, White	3:1	Y					Black on White	0.48	12.3			0.09	2.4	0.3	7.6	16 - 8 AWG		
<a href="#">H000X044H2M</a>	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .44" W x 8' L, Yellow							Black on Yellow											
<a href="#">H000X064H1M</a>	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, .64" W x 8' L, White							Black on White											
<a href="#">H000X064H2M</a>	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, .64" W x 8' L, Yellow							Black on Yellow											
<a href="#">H000X084H1M</a>	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, .84" W x 8' L, White	2:1	N					Black on White	0.87	22.5			0.32	8.1	0.54	13.7	4 - 1 AWG		
<a href="#">H000X084H2M</a>	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, .84" W x 8' L, Yellow							Black on Yellow											
<a href="#">H000X134H1M</a>	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, 1.34" W x 8' L, White							Black on White											
<a href="#">H000X134H2M</a>	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, 1.34" W x 8' L, Yellow							Black on Yellow											


Representative offering only, visit [www.panduit.com](http://www.panduit.com) for complete listing of products.

### Ordering Information



#### Non-Adhesive Polyester Component Labels

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Die-cut labels designed to provide maximum aesthetic quality and appearance
- Use for identifying patch panel, faceplates, punchdown blocks, and other network system hardware

 Non-Adhesive Polyester (Y1)

 -10°F to 311°F (-23°C to 155°C)

Part Number	Description	Labels per Cassette	Printer Compatibility				Color	Width		Height		Application	Std. Pkg. Qty.	Std. Ctn. Qty.
			MP75	MP100	MP200	MP300		In.	mm	In.	mm			
<a href="#">C195X040Y1M</a>	MP Cassette, Comp Label, Non-Adhesive Polyester, 1.95" W x .40" H, White	125						1.95	49.5	0.4	10.2	Single-gang faceplate	1	5
<a href="#">C261X035Y1M</a>	MP Cassette, Comp Label, Non-Adhesive Polyester, 2.61" W x .35" H, White	100	N	N	N	Y	White	2.61	66.3	0.35	8.9	4-port		

Representative offering only, visit [www.panduit.com](http://www.panduit.com) for complete listing of products.



#### Continuous Terminal Block Label Cassettes

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Print terminal block labels ranging in size from 0.24 inches to 0.38 inches

 Polyolefin (FJM)

 -40°F to 180°F (-40°C to 82°C)

Part Number	Description	Printer Compatibility				Print-On Area Color	Height		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
<a href="#">T024X000FJM-BK</a>	MP Cassette, Continuous Tape, Polyolefin, 0.24" W x 23' L, Black on White						0.229	5.82			1	5
<a href="#">T038X000FJM-BK</a>	MP Cassette, Continuous Tape, Polyolefin, 0.38" W x 23' L, Black on White	Y	Y	Y	Y	Black on White	0.347	8.82	23	7		

Representative offering only, visit [www.panduit.com](http://www.panduit.com) for complete listing of products.









### Ordering Information



#### Continuous Tape Cassettes

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Print custom pipe markers, voltage markers, signs, bin markers, and network ID labels on demand
- For flat label applications only

-  Vinyl Material (VXM & VPM)  -40°F to 194°F (-40°C to 90°C)
-  Polyester Material (YKM, BYM, BWM, BQM, BSM, BUM)  -40°F to 257°F (-40°C to 125°C)
-  Magnetic Material (MPM & MXM)  14°F to 104°F (-10°C to 40°C)


Part Number	Part Description	Printer Compatibility				Ribbon & Material Color	Width		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
<a href="#">T038X000VPM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 0.38" W x 23' L, Black on White.					Black on White	0.354	9.0	23	7.0		
<a href="#">T038X000VXM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 0.38" W x 23' L, Black on Yellow.					Black on Yellow			30	9.1		
<a href="#">T038X000YKM-BK</a>	MP Cassette, Continuous Tape, Polyester, 0.38" W x 30' L, Black on Clear.					Black on Clear	0.472	12.0	30	9.1		
<a href="#">T038X000BYM-WH</a>	MP Cassette, Continuous Tape, Polyester, 0.38" W x 30' L, White on Black.					White on Black						
<a href="#">T050X000VPM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 0.50" W x 23' L, Black on White.					Black on White	0.710	18.0	23	7.0		
<a href="#">T050X000VXM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 0.50" W x 23' L, Black on Yellow.					Black on Yellow			30	9.1		
<a href="#">T050X000YKM-BK</a>	MP Cassette, Continuous Tape, Polyester, 0.50" W x 30' L, Black on Clear.					Black on Clear	0.945	24.0	30	9.1	1	5
<a href="#">T050X000BYM-WH</a>	MP Cassette, Continuous Tape, Polyester, 0.50" W x 30' L, White on Black.					White on Black						
<a href="#">T075X000VPM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 0.75" W x 23' L, Black on White.					Black on White	0.945	24.0	30	9.1		
<a href="#">T075X000VXM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 0.75" W x 23' L, Black on Yellow.					Black on Yellow						
<a href="#">T075X000YKM-BK</a>	MP Cassette, Continuous Tape, Polyester, 0.75" W x 30' L, Black on Clear.					Black on Clear	1.471	36.0	30	9.1		
<a href="#">T075X000BYM-WH</a>	MP Cassette, Continuous Tape, Polyester, 0.75" W x 30' L, White on Black.					White on Black						
<a href="#">T100X000MPM-BK</a>	MP Cassette, Continuous Tape, Magnetic, 1.00" W x 4.9' L, Black on White.					Black on White	1.471	36.0	30	9.1		
<a href="#">T100X000MXM-BK</a>	MP Cassette, Continuous Tape, Magnetic, 1.00" W x 4.9' L, Black on Yellow.					Black on Yellow						
<a href="#">T100X000VPM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 1.00" W x 23' L, Black on White.					Black on White	1.471	36.0	30	9.1		
<a href="#">T100X000VXM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 1.00" W x 23' L, Black on Yellow.					Black on Yellow						
<a href="#">T100X000YKM-BK</a>	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, Black on Clear.					Black on Clear	1.471	36.0	30	9.1		
<a href="#">T100X000BQM-WH</a>	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, White on Blue.					White on Blue						
<a href="#">T100X000BSM-WH</a>	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, White on Green.					White on Green	1.471	36.0	30	9.1		
<a href="#">T100X000BUM-BK</a>	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, Black on Orange.					Black on Orange						
<a href="#">T100X000BWM-WH</a>	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, White on Red.					White on Red	1.471	36.0	30	9.1		
<a href="#">T100X000BYM-WH</a>	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, White on Black.					White on Black						
<a href="#">T150X000MPM-BK</a>	MP Cassette, Continuous Tape, Magnetic, 1.50" W x 4.9' L, Black on White.					Black on White	1.471	36.0	30	9.1		
<a href="#">T150X000MXM-BK</a>	MP Cassette, Continuous Tape, Magnetic, 1.50" W x 4.9' L, Black on Yellow.					Black on Yellow						
<a href="#">T150X000VPM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 1.50" W x 23' L, Black on White.					Black on White	1.471	36.0	30	9.1		
<a href="#">T150X000VXM-BK</a>	MP Cassette, Continuous Tape, Vinyl, 1.50" W x 23' L, Black on Yellow.					Black on Yellow						
<a href="#">T150X000YKM-BK</a>	MP Cassette, Continuous Tape, Polyester, 1.50" W x 30' L, Black on Clear.					Black on Clear	1.471	36.0	30	9.1		
<a href="#">T150X000BQM-WH</a>	MP Cassette, Continuous Tape, Polyester, 1.50" W x 30' L, White on Blue.					White on Blue						
<a href="#">T150X000BSM-WH</a>	MP Cassette, Continuous Tape, Polyester, 1.50" W x 30' L, White on Green.					White on Green	1.471	36.0	30	9.1		
<a href="#">T150X000BUM-BK</a>	MP Cassette, Continuous Tape, Polyester, 1.50" W x 30' L, Black on Orange.					Black on Orange						
<a href="#">T150X000BWM-WH</a>	MP Cassette, Continuous Tape, Polyester, 1.50" W x 30' L, White on Red.					White on Red	1.471	36.0	30	9.1		
<a href="#">T150X000BYM-WH</a>	MP Cassette, Continuous Tape, Polyester, 1.50" W x 30' L, White on Black.					White on Black						

Representative offering only, visit [www.panduit.com](http://www.panduit.com) for complete listing of products.

### PXE SERIES




**MP300/E**

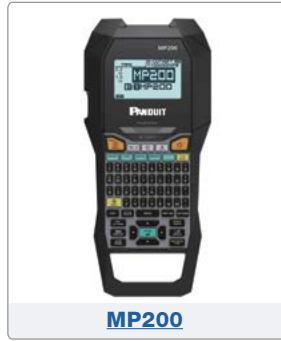

**MP200**



**MP100/E**

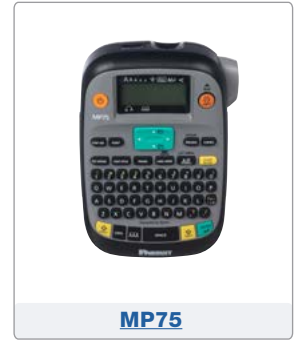

**MP75**

#### EMEA SALES OFFICES AND BRIEFING CENTERS

**London, United Kingdom**

One Oliver's Yard  
55-71 City Rd,  
Old Street,  
London EC1Y 1HQ  
Tel: +44 208  
601 7200

**Schwalbach, Germany**

Am Kronberger  
Hang 8  
65824 Schwalbach  
Tel: + 49 6196  
78530 20

**Milan, Italy**

Via Lepetit, 40,  
20020 Lainate  
Tel: +39 0293 17 31

**Brussels, Belgium**

Fountain Plaza,  
Belgicastraat 3  
1930 Zaventem  
Tel: +32 02  
466 86 60

**Moscow, Russia**

B. Serpukhovskaya,  
25 bld. 1  
115093 Moscow  
Tel: +7 499  
236 1441

**Arad, Romania**

Strada Ovidiu FN,  
Arad 310163,  
Tel: +40 357  
100 210

**Dubai, UAE**

3305 Shatha Tower  
Dubai Media City  
Dubai  
Tel: +971 4 3616933

**Doha, Qatar**

Al Mana Twin  
Towers, Office  
A, 12th floor,  
C-Ring Road, Doha  
Tel: +974 4491 0383

#### WORLDWIDE SUBSIDIARIES AND SALES OFFICES

**PANDUIT EUROPE LTD.**

London, UK  
cs-emea@panduit.com  
Phone: 44.20.8601.7200

**PANDUIT CANADA**

Markham, Ontario  
cs-cdn@panduit.com  
Phone: 800.777.3300

**PANDUIT SINGAPORE PTE. LTD.**

Republic of Singapore  
cs-ap@panduit.com  
Phone: 65.6305.7575

**PANDUIT JAPAN**

Tokyo, Japan  
cs-japan@panduit.com  
Phone: 81.3.6863.6000

**PANDUIT LATIN AMERICA**

Guadalajara, Mexico  
cs-la@panduit.com  
Phone: 52.33.3777.6000

**PANDUIT AUSTRALIA PTY. LTD.**

Victoria, Australia  
cs-aus@panduit.com  
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to [www.panduit.com/warranty](http://www.panduit.com/warranty)

For more information  
Visit us at [www.panduit.com](http://www.panduit.com)

Contact Customer Service by email: [cs-emea@panduit.com](mailto:cs-emea@panduit.com)  
or by phone: +44 208 601 7200