

MP200

PXE™ SERIES Mobile Printer

Product Bulletin

Enhanced Feature,
Cost-Effective Technology



PANDUIT™

EPSON
EXCEED YOUR VISION

PORTABLE LABEL PRINTER PARTNER

PXE™ SERIES Mobile Printers

Do your job smarter, faster and easier with PXE Series Mobile Printers. This full line of advanced identification printers combine Panduit's industry-leading performance and field-tested durability with Epson's world-class printing technology.



MP200 Mobile Label Printer

Better features and performance including PC connectivity for printing from a preferred software.

FEATURES:

- Shared MP Cassette Platform
- 180 dpi print resolution
- Automatic cutter with full or half cut
- Fast 1.2 in/sec print speed
- Up to 1.0 in wide label media
- Prints continuous labels only
- USB connectivity
- Prints from Easy-Mark Plus™ Software
- Magnetic attachment accessory*
- Rechargeable battery pack*
- Application specific label modes

*These features come with the MP200-KIT.

Easy-Mark Plus™ Software



- Common templates to easily create and print all electrical and network applications
- 11 languages included
- Available for USB flash drive, CD, web download or network server-based version
- Works with Panduit portable and desktop thermal transfer printers, Panduit embossing systems and other laser jet and ink jet printers
- A free 90 day trial version is available from www.panduit.com

PANDUIT™

EPSON

EXCEED YOUR VISION

PORTABLE LABEL PRINTER PARTNER

Epson™ Print Technology

Epson is a global technology leader dedicated to connecting people, things and information with efficient, compact and precision technologies.

Panduit™ Labeling and Software Expertise

Panduit creates leading-edge labeling solutions for electrical and network environments, from the data center to the telecom room, the jobsite to the plant floor.

Highlights



Continuous Self-Laminating Labels



Patch Panel / Face Plate Labels



Flag Labels



Continuous Tapes



Mixed Length Labels




High printing speed



Half cut function



Front loading cassette

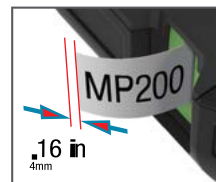

Less margin waste



Magnetic attachment



Label retention after cutting

Ordering Information

Printers and Accessories



MP200

Part Number	Description
MP200	The MP200 printer is a rugged, high performance, economical industrial printer. It features fast print speeds up to 1.2"/sec, a powered cutter allowing both full and half cuts, a large LCD backlit screen, custom label modes, barcodes and symbols. The MP200 prints continuous tapes up to 1.0" wide for network, electrical, and other industrial applications. It comes with the printer, one T100X000VPM-BK continuous label cassette, and quick reference card. For use globally.
MP200/E-KIT	The MP200/E-KIT printer is a rugged, high performance, economical industrial printer. It features fast print speeds up to 1.2"/sec, a powered cutter, a large LCD backlit screen, custom label modes, barcodes and symbols. The MP200 prints continuous tapes up to 1.0" wide for network, electrical, and other industrial applications. It comes with the printer, one T100X000VPM-BK continuous label cassette, hard carrying case, rechargeable battery pack, magnetic feet, USB cable, and power adapter. For use outside North America.
MP-CASE	The MP-CASE is a Replacement Hard Carrying Case designed for the MP200 and MP300 mobile printers. The case is RoHS Compliant. The case is 15.57 inches L x 11.74 inches W (395.4 mm x 298.4 mm). It is black and comes 1 per package.
PTR-CLN	Printer cleaning kit - contains (1) cleaning pen, (8) cleaning solution soaked wipes, (8) foam swabs pre-saturated with cleaning solution, MSDS, and cleaning instructions



MP200/E-KIT


Part Number	Description
EMPLUS-CD	Easy-Mark Plus™ Labeling Software, CD-ROM.
EMPLUS-DL	Easy-Mark Plus™ Labeling Software, online download.
EMPLUS-2GO	Easy-Mark Plus™ Portable Application, USB flash drive.
EMPLUS-SERVER	Easy-Mark Plus™ Labeling Software, networkable server based version.



EMPLUS


Easy-Mark Plus Labeling Software is sold separately, not included with PXE Printers

Ordering Information

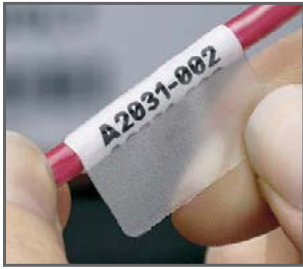

Continuous Self-Laminating Labels

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Self-laminating adhesive labels for wire/cable identification include a white print-on area and clear over-laminate

 Self-Laminating Vinyl (VA)

 -40°F to 150°F (-40°C to 66°C)


Part Number	Part Description	Printer Compatibility				Print-On Area Color	Width		Length		Print-On Area Width		Min. Cable O.D.		Max. Cable O.D.		Wire/Cable Size Range	Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m	In.	mm	In.	mm	In.	mm			
S000X100VAM	MP Cassette, Continuous Self-Lam Tape, Vinyl, 1.0" W x 26' L, White	N	Y	Y	Y	White	0.945	24	26.2	8.0	0.315	8	0.10	2.5	0.20	5.1	12 – 10 AWG	1	5


Representative offering only, visit www.panduit.com for complete listing of products.



Non-Laminated Label Cassettes

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Non-laminated adhesive labels for wire/cable identification

 Nylon Cloth (C1M)

 -65°F to 275°F (-54°C to 135°C)

Part Number	Part Description	Printer Compatibility				Print-On Area Color	Height		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
T050X000C1M-BK	MP Cassette, Continuous Tape, Nylon Cloth, 0.50" W x 19' L, Black on White	Y	N	Y	Y	Black on White	0.465	11.82	19	6	1	5
T075X000C1M-BK	MP Cassette, Continuous Tape, Nylon Cloth, 0.75" W x 19' L, Black on White						0.702	17.82				
T100X000C1M-BK	MP Cassette, Continuous Tape, Nylon Cloth, 1.00" W x 19' L, Black on White						0.938	23.82				


Representative offering only, visit www.panduit.com for complete listing of products.

Ordering Information




Continuous Heat Shrink Labels

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Non-adhesive flattened heat shrinkable polyolefin for wire/cable identification

 **Heat Shrinkable Polyolefin**
3:1 Heat Shrink Ratio (H1, H2)

Heat Shrinkable Polyolefin
2:1 Heat Shrink Ratio (HP, HX)

 **-40°F to 257°F**
(-40°C to 125°C)

-67°F to 257°F
(-55°C to 125°C)

Part Number	Part Description	Shrink Ratio	Mil Spec	Printer Compatibility				Ribbon & Material Color	Width		Length		Min. Cable O.D.		Max. Cable O.D.		Wire/Cable Size Range	Std. Pkg. Qty.	Std. Ctn. Qty.							
				MP75	MP100	MP200	MP300		In.	mm	Ft.	m	In.	mm	In.	mm										
H000X025H1M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .25" W x 8' L, White	3:1	Y	Y				Black on White	0.27	6.8			0.06	1.4	0.16	4.1	22 - 18 AWG	1	5							
H000X025H2M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .25" W x 8' L, Yellow							Black on Yellow																		
H000X034H1M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .34" W x 8' L, White							Black on White	0.37	9.3			0.07	1.9	0.22	5.7				16 - 8 AWG						
H000X034H2M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .34" W x 8' L, Yellow							Black on Yellow																		
H000X044H1M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .44" W x 8' L, White							Y	Y	Y			Black on White	0.48	12.3	8.2					2.5	0.09	2.4	0.3	7.6	16 - 8 AWG
H000X044H2M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .44" W x 8' L, Yellow												Black on Yellow													
H000X064HPM	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, .64" W x 8' L, White	2:1	N	N			N	Black on White	0.71	18.0			0.21	5.3	0.43	10.9	8 - 2 AWG									
H000X064HXM	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, .64" W x 8' L, Yellow							Black on Yellow																		
H000X084HPM	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, .84" W x 8' L, White							Black on White	0.87	22.5			0.32	8.1	0.54	13.7		4 - 1 AWG								
H000X084HXM	MP Cassette, 2:1 Continuous Heat Shrink Tubing, Polyolefin, .84" W x 8' L, Yellow							Black on Yellow																		

Representative offering only, visit www.panduit.com for complete listing of products.

Ordering Information



Continuous Terminal Block Label Cassettes

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Print terminal block labels ranging in size from 0.24 inches to 0.38 inches



Part Number	Part Description	Printer Compatibility				Print-On Area Color	Height		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
T024X000FJM-BK	MP Cassette, Continuous Tape, Polyolefin, 0.24" W x 23' L, Black on White					Black on White	0.229	5.82	23	7	1	5
T038X000FJM-BK	MP Cassette, Continuous Tape, Polyolefin, 0.38" W x 23' L, Black on White	Y	Y	Y	Y		0.347	8.82				

Representative offering only, visit www.panduit.com for complete listing of products.



**Like what you see?
Want more?**

Visit panduit.com/mobileprinters for the full offering of Panduit products

Ordering Information



Continuous Tape Cassettes

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Print custom pipe markers, voltage markers, signs, bin markers, and network ID labels on demand
- For flat label applications only

- Vinyl Material (VXM & VPM) -40°F to 194°F (-40°C to 90°C)
- Polyester Material (YKM, BYM, BWM, BQM, BSM, BUM) -40°F to 257°F (-40°C to 125°C)
- Magnetic Material (MPM & MXM) 14°F to 104°F (-10°C to 40°C)

Part Number	Part Description	Printer Compatibility				Ribbon & Material Color	Width		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
T038X000VPM-BK	MP Cassette, Continuous Tape, Vinyl, 0.38" W x 23' L, Black on White.					Black on White	0.354	9.0	23	7.0		
T038X000VXM-BK	MP Cassette, Continuous Tape, Vinyl, 0.38" W x 23' L, Black on Yellow.					Black on Yellow						
T038X000YKM-BK	MP Cassette, Continuous Tape, Polyester, 0.38" W x 30' L, Black on Clear.					Black on Clear			30	9.1		
T038X000BYM-WH	MP Cassette, Continuous Tape, Polyester, 0.38" W x 30' L, White on Black.					White on Black						
T050X000VPM-BK	MP Cassette, Continuous Tape, Vinyl, 0.50" W x 23' L, Black on White.					Black on White	0.472	12.0	23	7.0		
T050X000VXM-BK	MP Cassette, Continuous Tape, Vinyl, 0.50" W x 23' L, Black on Yellow.					Black on Yellow						
T050X000YKM-BK	MP Cassette, Continuous Tape, Polyester, 0.50" W x 30' L, Black on Clear.					Black on Clear			30	9.1		
T050X000BYM-WH	MP Cassette, Continuous Tape, Polyester, 0.50" W x 30' L, White on Black.					White on Black						
T075X000VPM-BK	MP Cassette, Continuous Tape, Vinyl, 0.75" W x 23' L, Black on White.					Black on White	0.710	18.0	23	7.0		
T075X000VXM-BK	MP Cassette, Continuous Tape, Vinyl, 0.75" W x 23' L, Black on Yellow.					Black on Yellow						
T075X000YKM-BK	MP Cassette, Continuous Tape, Polyester, 0.75" W x 30' L, Black on Clear.					Black on Clear			30	9.1	1	5
T075X000BYM-WH	MP Cassette, Continuous Tape, Polyester, 0.75" W x 30' L, White on Black.		Y	Y	Y	White on Black						
T100X000MPM-BK	MP Cassette, Continuous Tape, Magnetic, 1.00" W x 4.9' L, Black on White.					Black on White			4.9	1.5		
T100X000MXM-BK	MP Cassette, Continuous Tape, Magnetic, 1.00" W x 4.9' L, Black on Yellow.					Black on Yellow						
T100X000VPM-BK	MP Cassette, Continuous Tape, Vinyl, 1.00" W x 23' L, Black on White.					Black on White	0.945	24.0	23	7.0		
T100X000VXM-BK	MP Cassette, Continuous Tape, Vinyl, 1.00" W x 23' L, Black on Yellow.					Black on Yellow						
T100X000YKM-BK	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, Black on Clear.					Black on Clear						
T100X000BQM-WH	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, White on Blue.					White on Blue						
T100X000BSM-WH	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, White on Green.					White on Green						
T100X000BUM-BK	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, Black on Orange.					Black on Orange			30	9.1		
T100X000BWM-WH	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, White on Red.					White on Red						
T100X000BYM-WH	MP Cassette, Continuous Tape, Polyester, 1.00" W x 30' L, White on Black.					White on Black						

Representative offering only, visit www.panduit.com for complete listing of products.

PXE SERIES



MP300/E



MP200



MP100/E



MP75

EMEA SALES OFFICES AND BRIEFING CENTERS

London, United Kingdom

One Oliver's Yard
55-71 City Rd,
Old Street,
London EC1Y 1HQ
Tel: +44 208
601 7200

Schwalbach, Germany

Am Kronberger
Hang 8
65824 Schwalbach
Tel: + 49 6196
78530 20

Milan, Italy

Via Lepetit, 40,
20020 Lainate
Tel: +39 0293 17 31

Brussels, Belgium

Fountain Plaza,
Belgicastraat 3
1930 Zaventem
Tel: +32 02
466 86 60

Moscow, Russia

B. Serpukhovskaya,
25 bld. 1
115093 Moscow
Tel: +7 499
236 1441

Arad, Romania

Strada Ovidiu FN,
Arad 310163,
Tel: +40 357
100 210

Dubai, UAE

3305 Shatha Tower
Dubai Media City
Dubai
Tel: +971 4 3616933

Doha, Qatar

Al Mana Twin
Towers, Office
A, 12th floor,
C-Ring Road, Doha
Tel: +974 4491 0383

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT EUROPE LTD.

London, UK
cs-emea@panduit.com
Phone: 44.20.8601.7200

PANDUIT CANADA

Markham, Ontario
cs-cdn@panduit.com
Phone: 800.777.3300

PANDUIT SINGAPORE PTE. LTD.

Republic of Singapore
cs-ap@panduit.com
Phone: 65.6305.7575

PANDUIT JAPAN

Tokyo, Japan
cs-japan@panduit.com
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA

Guadalajara, Mexico
cs-la@panduit.com
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.

Victoria, Australia
cs-aus@panduit.com
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information
Visit us at www.panduit.com

Contact Customer Service by email: cs-emea@panduit.com
or by phone: +44 208 601 7200