












Data Center Fiber Pre-terminated Solution




MULTIMODE OM4

Pre-terminated solution makes deployment easy.
Pre-terminated solution can be reused for future migration.

OM4 SOLUTION DEPLOYMENT

 <p>LC Uniboot Push Pull Patch Cord</p>	<p>Rear Cable Manager</p>  <p>Patch Panel</p>  <p>Universal Cassette</p>  <p>Front Cable Manager</p> 	<p>MPO Method B Female to Female Trunk</p> 	<p>Rear Cable Manager</p>  <p>Patch Panel</p>  <p>Universal Cassette</p>  <p>Front Cable Manager</p> 	 <p>LC Uniboot Push Pull Patch Cord</p>
<p>FZ2TLUCUCONM001 FZ2TLUCUCONM002 FZ2TLUCUCONM003 FZ2TLUCUCONM005 FZ2TLUCUCONM010 FZ2TLUCUCONM015</p>	<p>Patch Panel w/ Rear Cable Manager: CFAPPBL1 FQCRCM Universal Cassette: FCWZO-12-10U FCWZO-24-10U Front Cable Manager: FPFPC1</p>	<p>FWZTL55Y005M005 FWZTL55Y005M010 FWZTL55Y005M015 FWZTL55Y005M020 FWZTL55Y005M030 FWZTL55Y005M050 FWZTL55Y005M080</p>	<p>Patch Panel w/ Rear Cable Manager: CFAPPBL1 FQCRCM Universal Cassette: FCWZO-12-10U FCWZO-24-10U Front Cable Manager: FPFPC1</p>	<p>FZ2TLUCUCONM001 FZ2TLUCUCONM002 FZ2TLUCUCONM003 FZ2TLUCUCONM005 FZ2TLUCUCONM010 FZ2TLUCUCONM015</p>

Refer below description and pricing:

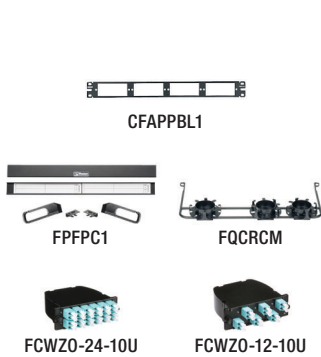

Part Number	Part Description	Std. Pkg. Qty.	Std. Ctn. Qty.
Patch Panels			
CFAPPBL1	Flat fiber patch panel which accepts four QuickNet™ Universal Cassettes	1	10
Front and Rear Cable Manager			
FPFPC1	1 RU fiber patch field protection cover. Includes a labeling card and D-rings. Not compatible with angled patch panels	1	10
FQCRCM	QuickNet™ Cassette Patch Panel Rear Cable Manager, manages up to one metre of slack for sixteen MTP interconnect cables	1	10
Universal Cassettes			
FCWZO-12-10U	QuickNet™ Multimode 12-fiber, Optimized IL, MPO to 6-port Duplex LC adapter cassette, Universal, used with Method B trunk	1	10
FCWZO-24-10U	QuickNet™ Multimode 24-fiber, Optimized IL, MPO to 12-port Duplex LC adapter cassette, Universal, used with Method B trunk	1	10
MPO Method B Female to Female Trunk			
FWZTL55Y005M005	OM4 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Optimized IL, Pulling eye end A, 5m	1	10
FWZTL55Y005M010	OM4 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Optimized IL, Pulling eye end A, 10m	1	10
FWZTL55Y005M015	OM4 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Optimized IL, Pulling eye end A, 15m	1	10
FWZTL55Y005M020	OM4 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Optimized IL, Pulling eye end A, 20m	1	10
FWZTL55Y005M030	OM4 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Optimized IL, Pulling eye end A, 30m	1	10
FWZTL55Y005M050	OM4 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Optimized IL, Pulling eye end A, 50m	1	10
FWZTL55Y005M080	OM4 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Optimized IL, Pulling eye end A, 80m	1	10
LC Uniboot Push Pull Patch Cords			
FZ2TLUCUCONM001	OM4 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 1m	1	10
FZ2TLUCUCONM002	OM4 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 2m	1	10
FZ2TLUCUCONM003	OM4 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 3m	1	10
FZ2TLUCUCONM005	OM4 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 5m	1	10
FZ2TLUCUCONM010	OM4 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 10m	1	10
FZ2TLUCUCONM015	OM4 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 15m	1	10

**represent the length of the patch cord






 





Data Center Fiber Pre-terminated Solution




SINGLEMODE OS2

Pre-terminated solution makes deployment easy.
Pre-terminated solution can be reused for future migration.

OS2 SOLUTION DEPLOYMENT

 <p>LC Uniboot Push Pull Patch Cord</p>	<p>Rear Cable Manager</p>  <p>Patch Panel</p>  <p>Universal Cassette</p>  <p>Front Cable Manager</p> 	<p>MPO Method B Female to Female Trunk</p> 	<p>Rear Cable Manager</p>  <p>Patch Panel</p>  <p>Universal Cassette</p>  <p>Front Cable Manager</p> 	 <p>LC Uniboot Push Pull Patch Cord</p>
<p>F92TLUCUCONM001 F92TLUCUCONM002 F92TLUCUCONM003 F92TLUCUCONM005 F92TLUCUCONM010 F92TLUCUCONM015</p>	<p>Patch Panel w/ Rear Cable Manager: CFAPPBL1 FQCRCM Universal Cassette: FCW9N-12-10U FCW9N-24-10U Front Cable Manager: FPFPC1</p>	<p>FW9TL55B005M005 FW9TL55B005M010 FW9TL55B005M015 FW9TL55B005M020 FW9TL55B005M030 FW9TL55B005M050 FW9TL55B005M080</p>	<p>Patch Panel w/ Rear Cable Manager: CFAPPBL1 FQCRCM Universal Cassette: FCW9N-12-10U FCW9N-24-10U Front Cable Manager: FPFPC1</p>	<p>F92TLUCUCONM001 F92TLUCUCONM002 F92TLUCUCONM003 F92TLUCUCONM005 F92TLUCUCONM010 F92TLUCUCONM015</p>

Refer below description and pricing:

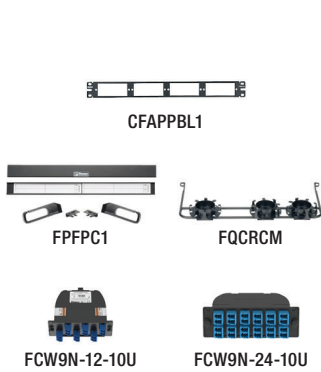

Part Number	Part Description	Std. Pkg. Qty.	Std. Ctn. Qty.
Patch Panels			
CFAPPBL1	Flat fiber patch panel which accepts four QuickNet™ Universal Cassettes	1	10
Front and Rear Cable Manager			
FPFPC1	1 RU fiber patch field protection cover. Includes a labeling card and D-rings. Not compatible with angled patch panels	1	10
FQCRCM	QuickNet™ Cassette Patch Panel Rear Cable Manager, manages up to one metre of slack for sixteen MTP interconnect cables	1	10
Universal Cassettes			
FCW9N-12-10U	QuickNet™ Singlemode 12-fiber, Standard IL, MPO to 6-port Duplex LC adapter cassette, Universal, used with Method B trunk	1	10
FCW9N-24-10U	QuickNet™ Singlemode 24-fiber, Standard IL, MPO to 12-port Duplex LC adapter cassette, Universal, used with Method B trunk	1	10
MPO Method B Female to Female Trunk			
FW9TL55B005M005	OS2 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Standard IL, Pulling eye end A, 5m	1	10
FW9TL55B005M010	OS2 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Standard IL, Pulling eye end A, 10m	1	10
FW9TL55B005M015	OS2 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Standard IL, Pulling eye end A, 15m	1	10
FW9TL55B005M020	OS2 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Standard IL, Pulling eye end A, 20m	1	10
FW9TL55B005M030	OS2 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Standard IL, Pulling eye end A, 30m	1	10
FW9TL55B005M050	OS2 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Standard IL, Pulling eye end A, 50m	1	10
FW9TL55B005M080	OS2 12-fiber trunk, LSZH, MPO Female to MPO Female, Method B, Standard IL, Pulling eye end A, 80m	1	10
LC Uniboot Push Pull Patch Cords			
F92TLUCUCONM001	OS2 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 1m	1	10
F92TLUCUCONM002	OS2 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 2m	1	10
F92TLUCUCONM003	OS2 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 3m	1	10
F92TLUCUCONM005	OS2 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 5m	1	10
F92TLUCUCONM010	OS2 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 10m	1	10
F92TLUCUCONM015	OS2 Duplex LC 2mm, LSZH, Uniboot, Std Polarity Opt IL, patch cord, 15m	1	10

**represent the length of the patch cord