


Increase Rack Power Flexibility

Panduit G5 iPDUs - EMEA

Featuring Combination Outlets for Higher Outlet Density and Increased Power Capacity

Digitization has created the need to maximize IT equipment in the rack.

The G5 iPDU 4-in-1 combination outlets provide the ultimate in connection flexibility allowing a single receptacle to be used as a C13/C15 or a C13/C15/C19/C21, making sure connection types are available when needed most. The 4-in-1 combination outlets accept Panduit dual-locking power cords eliminating accidental disconnects. The G5 PDUs also feature higher power capacities than ever before, allowing more equipment to be powered from a single PDU. Available in Monitored Input (MI), Monitored Switched (MS), or Monitored & Switched per Outlet (MSPO) varieties with power capacities ranging from 8.6KW to 43.5KW.

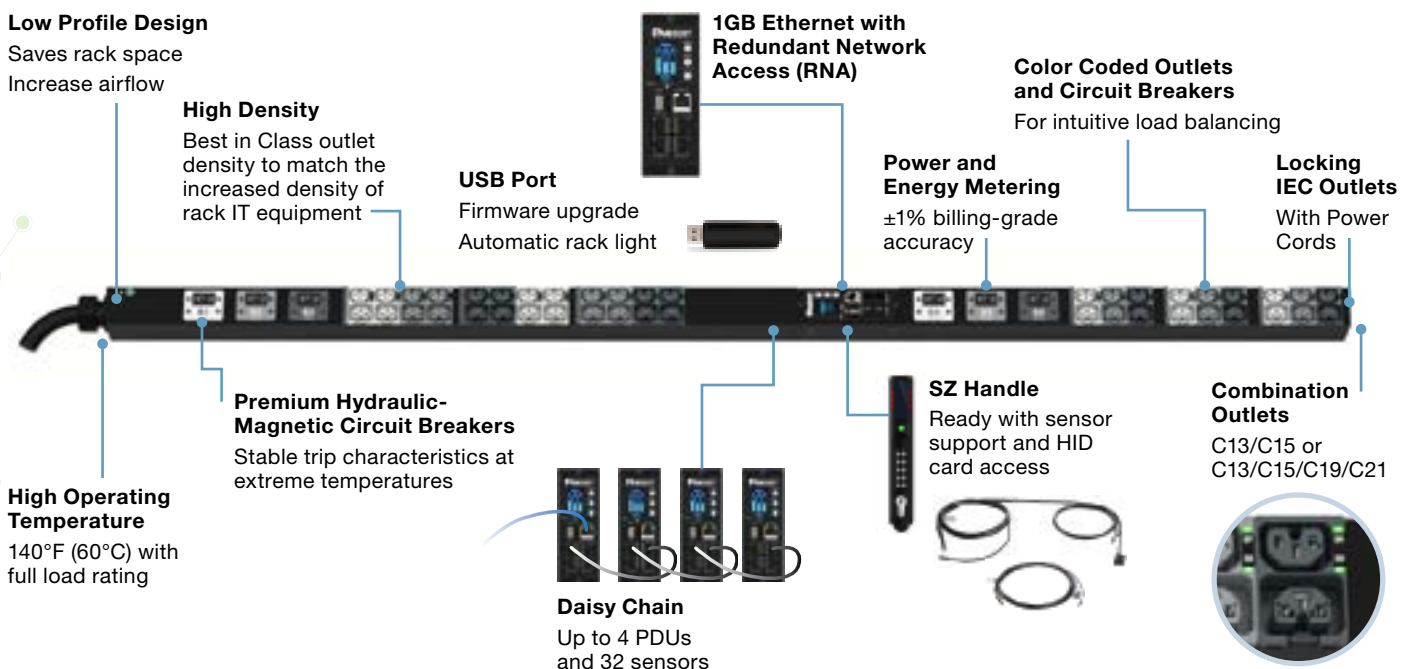

[PRODUCTS & SPECIFICATIONS](#) ▶

Power Distribution Units

Part Number	Voltage & Phase	Input Current per Phase	Input Plug	Form Factor	Circuit Breakers	Outlet Count	Outlet Configuration	Length
Monitored Input – MI Series								
P48D23M	230/415VAC, 3-Phase	16A	IEC 60309 3P+N+E 6h 20A/16A (IP44)	OU MID	-	48	(24)C13, C15, (24)C13, C15, C19, C21	1490mm
P48D20M		32A	IEC 60309 3P+N+E 6h 30A/32A (IP44)	OU FULL	6			1780mm
P42D21M		63A	IEC 60309 3P+N+E 6h 60/63 (IP44)	OU FULL	12	42	(21)C13, C15, (21)C13, C15, C19, C21	1826mm
Monitored Switched – MS Series								
P48E23M	230/415VAC, 3-Phase	16A	IEC 60309 3P+N+E 6h 20A/16A (IP44)	OU MID	-	48	(24)C13, C15, (24)C13, C15, C19, C21	1490mm
P48E20M		32A	IEC 60309 3P+N+E 6h 30A/32A (IP44)	OU FULL	6			1780mm
P48E25M		63A	EC 60309 3P+N+E 6h 60/63A (IP44)	OU FULL	12	12	1780mm	
Monitored Switched Per Outlet – MSPO Series								
P48G33M	230/415VAC, 3-Phase	16A	IEC 60309 3P+N+E 6h 20A/16A (IP44)	OU MID	-	48	(24)C13, C15, (24)C13, C15, C19, C21	1490mm
P48G30M		32A	IEC 60309 3P+N+E 6h 30A/32A (IP44)	OU FULL	6			1780mm
P42G21M		63A	IEC 60309 3P+N+E 6h 60A/63A (IP44)	OU FULL	12	42	(21)C13, C15, (21)C13, C15, C19, C21	1826mm
Monitored Per Outlet – MPO Series								
Built to Order								

Related Products

Part Number	Description
Environmental Sensors	
EA001	Temperature Environmental Sensor
EB001	Temperature and Humidity Sensor
EC001	3 Temperature and Humidity Sensor
ED001	Water Sensor Rope Type
Locking Power Cords	
LPCA11-X	2FT, Black, 17 AWG, 10A/250V, Locking Power Cord, IEC C14 to IEC C13, 10 Pack
LPCA12-X	4FT, Black, 17 AWG, 10A/250V, Locking Power Cord, IEC C14 to IEC C13, 10 Pack
LPCB11-X	2FT, Black, 15 AWG, 16A/250V, Locking Power Cord, IEC C20 to IEC C19, 10 Pack
LPCB12-X	4FT, Black, 15 AWG, 16A/250V, Locking Power Cord, IEC C20 to IEC C19, 10 Pack

Part Number	Description
Racks & Enclosures	
R2P	2 Post Rack, 45RU, #12-24 Threaded E-Rails, Aluminum, Black
R2PPDUB	2-Post Rack PDU Mounting Bracket Kit, Steel, Black
AR4PCN	4-Post Rack, Adjustable Depth, 45RU, Cage Nut E-Rails, Black
CVPDUB	4-Post Rack PDU Mounting Bracket Kit, Steel, Black
XGL84222W	FlexFusion XGL Cabinet, 800 x 42RU x 1200, White
XGL84822W	FlexFusion XGL Cabinet, 800 x 48RU x 1200, White
Asset Management & Monitoring	
SZC-PEIA1Y/3Y	Power & environmental infrastructure asset, 1-year or 3-year subscriptions
SZC-ITIA1Y/3Y	IT infrastructure asset, 1-year or 3-year subscriptions

To learn more about
Panduit G5 iPDUs,
scan the QR code.

